

## Round Media



### Description

Bulkhead pass-through connectors are passive male to female connectors within a threaded metal housing. These connectors increase system modularity and ease installation in through-panel applications.


### Features

- Male to female bulkhead passthru provides flexibility in thru-panel installations
- Thick cable provides 5-pin mini version for use with DeviceNet wiring
- Thin cable provides standard 5-pin DC micro version allows use for a variety of pin-count configurations

### Specifications

	Mini	Micro
<b>Mechanical</b>		
Shell and Lockout Material	Nickel-plated brass	
Connector Insert Material	PVC	Nylon
Gasket	Neoprene	
Thrust Washer	Nylon	Steel Alloy
Contact Material	Gold-plated palladium nickel	
<b>Electrical</b>		
Assembly Rating	600V, 8 A	250V, 4 A
<b>Environmental</b>		
Enclosure Type Rating	IP 67	
Operating Temperature—C (F)	-20...+105° (-4...+221°)	-20...+80° (-4...+176°)

### Dimensions—mm (in)

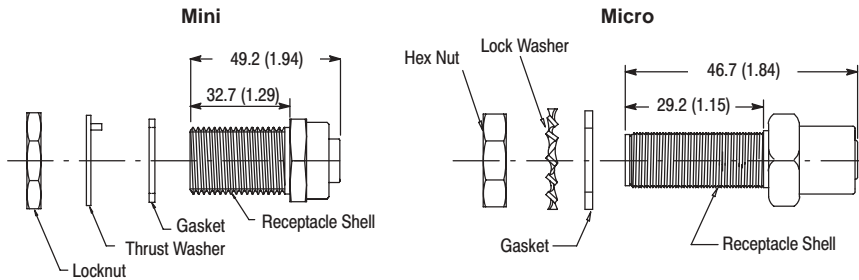

Dimensions are approximate. Illustrations are not drawn to scale.

### Product Selection

Connection Type	Media Use	Cat. No.
Mini 5-pin	Thick or Thin	<b>1485A-CXN5-M5</b>
Micro 5-pin	Thin	<b>1485A-CXR5-D5</b>

**Note:** Stainless steel mini version may be ordered by adding "S" to the catalog number (e.g., **1485AS-CXN5-M5**).