

Mini Style




Specifications

Certifications	UL recognized and CSA certified
Mechanical	
Material	Nickel-plated brass
Lock Nut	Nickel-plated brass
Contacts	Gold-plated palladium/nickel
Gasket	Neoprene
Thrust Washer	Nylon
Connector Insert Material	PVC
Environmental	
Enclosure Type Rating	NEMA 4, 6P, 12, 13; IP 67; 1200 psi washdown
Operating Temperature—C (F)	-20...+105° (-4...+221°)

Features

- Male to female bulkhead passthru provides flexibility in thru-panel installations
- 3- through 6-pin mini versions for use in multiple applications with standard wiring or DeviceNet implementations


Dimensions—mm (in)

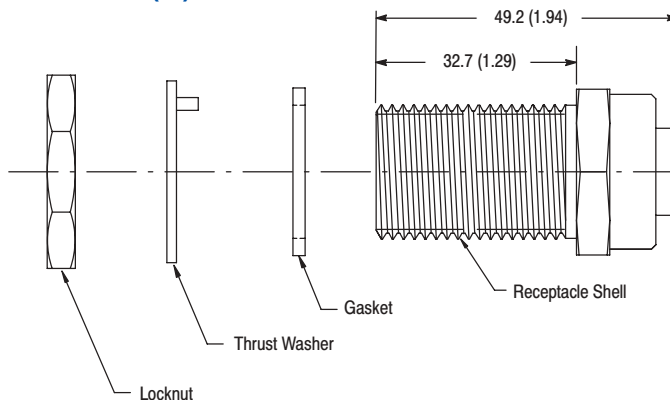

Dimensions are approximate. Illustrations are not drawn to scale.

Pinout

Face View Pinout

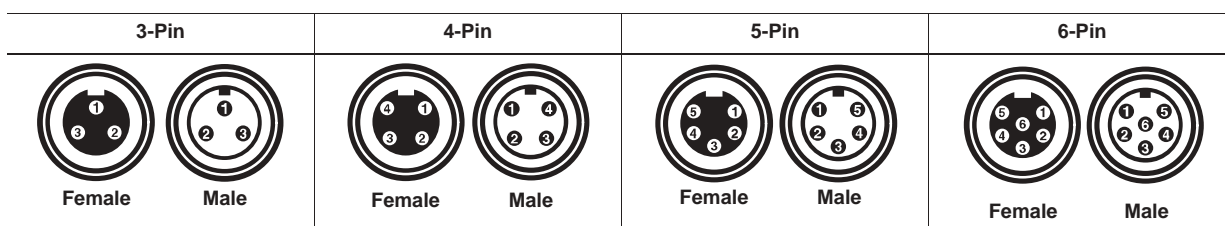

Product Selection

Bulkhead Pass-thru

Pin Count	Assembly Rating	Cat. No.
3-Pin	600V 13 A	889A-CXN3-M3
4-Pin	600V 10 A	889A-CXN4-M4
5-Pin	600V 8 A	1485A-CXN5-M5
6-Pin	600V 8 A	889A-CXN6-M6

Note: Stainless steel versions may be ordered by adding an "S" to the Cat. No. (i.e. **889AS-CXN4-M4**).