

EAC Micro Style



4-Pin EAC Micro Cordset

Features

- Ratcheting coupling nut
- Highly visible yellow PVC jacket offers good oil and chemical resistance


Specifications

Certifications	UL recognized and CSA certified
Mechanical	
Coupling Nut Material	Epoxy coated zinc
Connector Material	Molded oil-resistant polyurethane body
Contacts	Gold over nickel-plated brass
Cable	Yellow oil-resistant PVC jacket, 22AWG conductors, 300V, UL recognized and CSA certified
Cable Diameter	5 mm (0.21 in)
Electrical	
Cable Rating	300V
Assembly Rating	300V, 3 A
Environmental	
Enclosure Type Rating	IP 67
Operating Temperature—C (F)	-40...+90° (-40...+194°)

Pinout and Color Code

Color Code	Face View Pinout	
	4-Pin	
	Female	
A	1 Brown 2 Blue	3 Not Used 4 Green/Yellow
B	1 Brown 2 Blue	3 Black 4 Green/Yellow

Dimensions—mm (in)

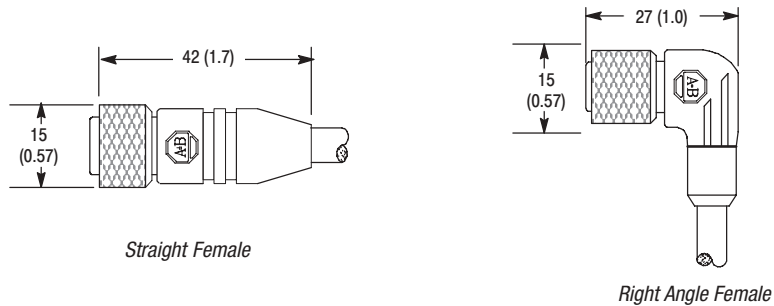

Dimensions are approximate. Illustrations are not drawn to scale.

Product Selection

Pin Count	Assembly Rating	Color Code	Cat. No.	
			Straight Female	Right Angle Female
3-Pin	22 AWG 300V 3 A	A	889B-F3AC-*	889B-R3AC-*
4-Pin		B	889B-F4AC-*	889B-R4AC-*

* Replace symbol with 2 (2m), 5 (5m) or 10 (10m) for standard cable lengths.