

Splitter, Pico Style

Pico to Pico, DC Micro to Pico

Pico Style



Splitter


Features

- Two 3-pin female pico to one 4-pin DC micro connector allows simplification of wiring
- PUR body offers good oil and chemical resistance
- Ratcheting coupling nuts for vibration resistance

Specifications

Certifications	UL recognized and CSA certified
Mechanical	
Material	Black PUR
Connector Insert	PUR
Receptacle Shell Material	Nickel-plated brass
Contacts	Gold-plated palladium/nickel
O-Ring	Viton®
Electrical	
Assembly Rating	60V AC/75V DC, 4 A
Environmental	
Enclosure Type Rating	IP 67; NEMA 6P
Operating Temperature—C (F)	-0...+85° (-32...+185°)

Dimensions—mm (in)

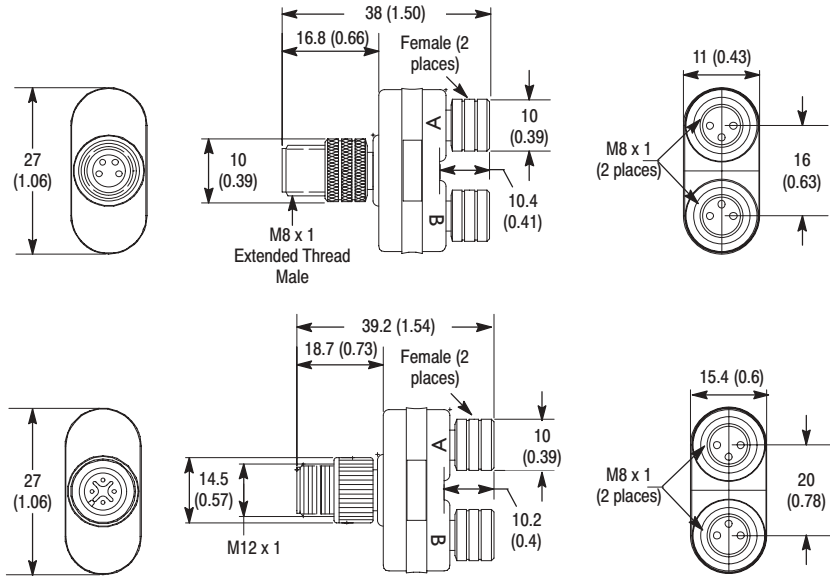

Dimensions are approximate. Illustrations are not drawn to scale.

Pinout

Pinout	Face View Pinout	Face View Pinout
	A	B
	<p style="text-align: center;">Female Female Male</p>	<p style="text-align: center;">Female Female Male</p>
	3-Pin Pico Female to 4-Pin Pico Male	3-Pin Pico Female to 4-Pin DC Micro Male

Product Selection

Splitters

Connector	Wiring Diagram	Assembly Rating	Pinout	Cat. No.
Standard Wiring Pico to Pico		60V AC/75V DC 4 A	A	898P-32YY-PM4
Standard Wiring Pico to DC Micro			B	898P-32YY-DM4