

Splitter, AC Micro Style

MDSA Module Wiring

AC Micro Style



Splitter, AC Micro


Features

- Splitter designed for use with Bulletin 198 MDSA AC modules
- PUR body offers good oil and chemical resistance
- Ratcheting coupling nut for vibration resistance

Specifications


Certifications	UL recognized and CSA certified
Mechanical	
Material	Black PUR
Connector Insert	PUR
Receptacle Shell Material	Nickel-plated brass
Contacts	Brass, gold over nickel plating
O-Ring	Viton®
Electrical	
Assembly Rating	300V, 3 A
Environmental	
Enclosure Type Rating	IP 67; NEMA 6P
Operating Temperature—C (F)	-30...+105° (-22...+221°)

Dimensions—mm (in)

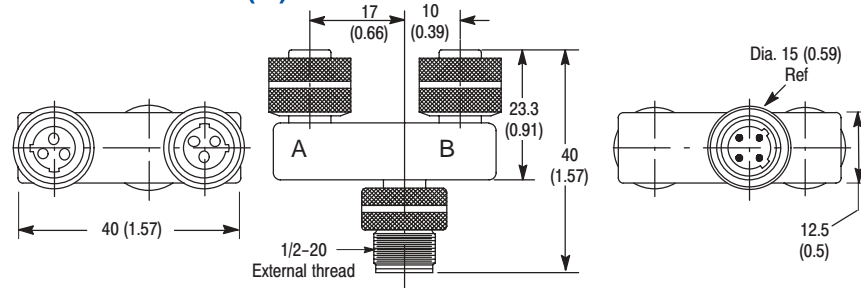

Dimensions are approximate. Illustrations are not drawn to scale.

Pinout

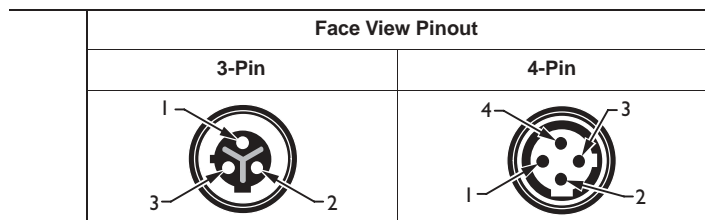

Product Selection

Splitters 

Type	Wiring Diagram	Assembly Rating	Cat. No.
Standard Wiring	<p>A Female 1 2 3</p> <p>B Female 1 2 3</p> <p>4 3 2 1 Male Connector</p>	300V 3 A	898R-33PYX-R3