

ModCenter PLUS

A Fast Delivery Program — Order a combination starter to your specifications


ModCenter PLUS Program — Authorized Allen-Bradley distributors are certified through specialized training to modify NEMA Combination Starters to your specifications. Combination Starters configured with Allen-Bradley modification kits maintain all UL/cUL and CSA Listings.

ModCenter PLUS Kits

- 1 Auxiliary Contact (Contactor)
- 2 Surge Suppressor
- 3 Coil
- 4 Fuse Clips
- 5 Terminal Blocks
- 6 Pilot Light
- 7 Push-to-Test Pilot Light
- 8 Selector Switch
- 9 Push Button
- 10 Transformer with Top-Mounted Fuse Block
- 11 Phase Monitor
- 12 Handles
- 13 Auxiliary Contacts (Disconnect)
- 14 SMP Overload Relay

ModCenter PLUS Kits (Not Shown)


- 15 Circuit Breaker
- 16 Auxiliary Contact (Circuit Breaker)
- 17 Auxiliary Contact (Eutectic Overload Relay)
- 18 Door Safety Hardware
- 19 Timing Relay
- 20 Control Relay
- 21 Fuse Cover (Disconnect)

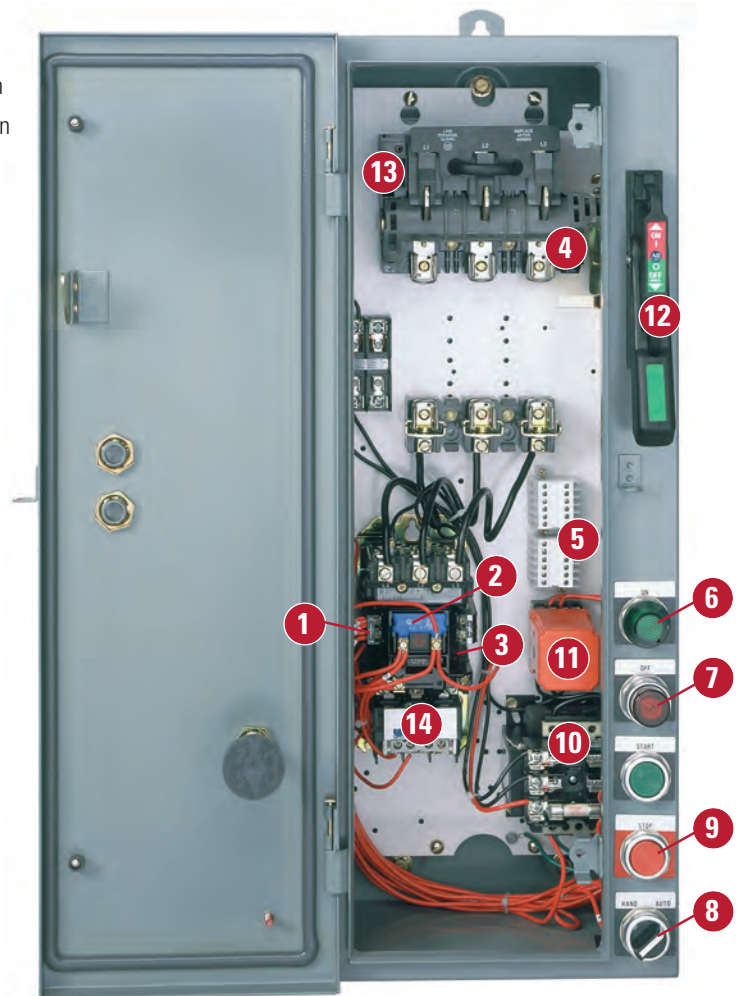

LISTEN.
THINK.
SOLVE.™

Program Benefits

Fast Ship — Same-day delivery available on a wide range of customized NEMA Combination Starters

Built to Order — Combination Starters are configured with stocked  kits to meet unexpected customer demand

Quality Service — Modifications are performed by Allen-Bradley distributors who have been certified through specialized training

Flexibility — Offers a wide variety of enclosure, starter, and disconnect types. Open type contactors and starters are also available with various coil voltage and overload relay options.

Enclosure Types

Type 1 Painted Metal Enclosure

- General Indoor Use
- Screw Fasteners
- External Overload Relay Reset
- Molded Handle
- Painted Metal Handle (Optional)

Type 3R Painted Metal Enclosure

- Rainproof
- Screw Fasteners
- External Overload Relay Reset
- Molded Handle
- Painted Metal Handle (Optional)
- Extra Capacity Enclosure

Starter Types

Bulletin Number	Description	NEMA Starter Size
506	Reversing Combination Starter w/Disconnect	0...5
507	Reversing Combination Starter w/Circuit Breaker	0...5
512	Non-Reversing Combination Starter w/Disconnect	0...5
513	Non-Reversing Combination Starter w/Circuit Breaker	0...5
522	Multi-Speed Combination Starter w/Disconnect	1...5
523	Multi-Speed Combination Starter w/Circuit Breaker	1...5
1232X	Pump Control Panel w/Disconnect	1...5
1233X	Pump Control Panel w/Circuit Breaker	1...5



Enhanced
Multi-rated
Type 3R/4/12
Enclosure

Type 3R/4/12 Painted Metal Enclosure

- Rainproof/Watertight/Dust-tight Screw Fasteners
- Door Safety Hardware (Optional)
- External Overload Relay Reset
- Available w/ Molded or Metal Handle

Type 4/4X Non-Metallic Enclosure

- Watertight/Corrosion Resistant
- Screw Fasteners
- External Overload Reset
- Molded Handle

Type 4/4X Stainless Steel Enclosure

- Watertight/Corrosion Resistant
- Stainless Steel Enclosure
- Screw Fasteners
- External Overload Reset
- Stainless Steel Handle