

Bulletin 140G 3P Flange Cable Operator



Simplified Selection, Faster Installation and Improved Access

Features and Benefits

Space Savings

- Cable can be easily routed under most enclosure flanges
- Reduces overall footprint and increases usable panel space

Terminal Access

- Ability to install 140G-*TH3H line and load terminal covers without disassembly
- Compatible with all terminal lug options including extended and spreader options

Flexible Cable

- Reduced bend radius for shallow enclosures
- Mechanism and cable are factory tuned
- Easier assembly/installation



The new Bulletin 140G Flange Cable Operator improves panel space efficiency while simplifying selection and installation.

Flange Cable Operator

The new Bulletin 140G Flange Cable Operator improves panel space efficiency by using a more flexible cable that can fit under the flange and a smaller bail mechanism that takes less space below the circuit breaker. The new mechanism also improves access to the circuit breaker terminals, without disassembly. This enables installation of line- and load-side terminal covers and all lug options, including extended and spreader lugs.

Optional EZ Plate

The optional "EZ Plate" minimizes installation steps by allowing preassembly of the circuit breaker actuation mechanism prior to mounting into control panel and simplifies mounting by providing greater visibility of fastener locations.



LISTEN.
THINK.
SOLVE.™

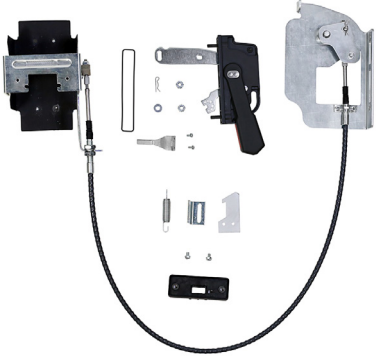
Catalog Explanation

Flange-mounted Cable Operator – 3 Pole only

140G - G - F CX B 04

Bulletin Number		Frame / Rating		Flange		Handle Type		Bail		Cable Length	
Code	Description	Code	Description	Code	Description	Code	Description	Code	Description	Code	Description
140G	Global Molded Case Circuit Breaker	G	125A	F	Flange Cable	CX	Non-metallic (plastic)	B	Bail	03	3 ft. [0.91 m]
		H	125A			MX	Painted Metal			04	4 ft. [1.3 m]
		I	225A			CS	Stainless Steel			06	6 ft. [1.9 m]
		J	250A							10	10 ft. [3.0 m]
		K	400A								

Product Selection

Description	Frame Size	Handle Type	Cable Length	Catalog Number	Cable Length	Catalog Number
<ul style="list-style-type: none"> • For use with NEMA-Style Flange Enclosures • Includes Handle, Bail Mechanism, Cable & Assembly Hardware • Pre-assembled for ease of installation  <p>Complete Kit</p>	G	Non-metallic Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-G-FCXB03	6 ft. [1.9 m]	140G-G-FCXB06
			4 ft. [1.3 m]	140G-G-FCXB04	10 ft. [3.0 m]	140G-G-FCXB10
		Painted Metal Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-G-FMXB03	6 ft. [1.9 m]	140G-G-FMXB06
			4 ft. [1.3 m]	140G-G-FMXB04	10 ft. [3.0 m]	140G-G-FMXB10
		Stainless Steel Handle, Type 4/4X	3 ft. [0.91 m]	140G-G-FCSB03	6 ft. [1.9 m]	140G-G-FCSB06
			4 ft. [1.3 m]	140G-G-FCSB04	10 ft. [3.0 m]	140G-G-FCSB10
	H	Non-metallic Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-H-FCXB03	6 ft. [1.9 m]	140G-H-FCXB06
			4 ft. [1.3 m]	140G-H-FCXB04	10 ft. [3.0 m]	140G-H-FCXB10
		Painted Metal Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-H-FMXB03	6 ft. [1.9 m]	140G-H-FMXB06
			4 ft. [1.3 m]	140G-H-FMXB04	10 ft. [3.0 m]	140G-H-FMXB10
		Stainless Steel Handle, Type 4/4X	3 ft. [0.91 m]	140G-H-FCSB03	6 ft. [1.9 m]	140G-H-FCSB06
			4 ft. [1.3 m]	140G-H-FCSB04	10 ft. [3.0 m]	140G-H-FCSB10
	I	Non-metallic Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-I-FCXB03	6 ft. [1.9 m]	140G-I-FCXB06
			4 ft. [1.3 m]	140G-I-FCXB04	10 ft. [3.0 m]	140G-I-FCXB10
		Painted Metal Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-I-FMXB03	6 ft. [1.9 m]	140G-I-FMXB06
			4 ft. [1.3 m]	140G-I-FMXB04	10 ft. [3.0 m]	140G-I-FMXB10
		Stainless Steel Handle, Type 4/4X	3 ft. [0.91 m]	140G-I-FCSB03	6 ft. [1.9 m]	140G-I-FCSB06
			4 ft. [1.3 m]	140G-I-FCSB04	10 ft. [3.0 m]	140G-I-FCSB10
	J	Non-metallic Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-J-FCXB03	6 ft. [1.9 m]	140G-J-FCXB06
			4 ft. [1.3 m]	140G-J-FCXB04	10 ft. [3.0 m]	140G-J-FCXB10
		Painted Metal Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-J-FMXB03	6 ft. [1.9 m]	140G-J-FMXB06
			4 ft. [1.3 m]	140G-J-FMXB04	10 ft. [3.0 m]	140G-J-FMXB10
		Stainless Steel Handle, Type 4/4X	3 ft. [0.91 m]	140G-J-FCSB03	6 ft. [1.9 m]	140G-J-FCSB06
			4 ft. [1.3 m]	140G-J-FCSB04	10 ft. [3.0 m]	140G-J-FCSB10
K	Non-metallic Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-K-FCXB03	6 ft. [1.9 m]	140G-K-FCXB06	
		4 ft. [1.3 m]	140G-K-FCXB04	10 ft. [3.0 m]	140G-K-FCXB10	
	Painted Metal Handle, Type 1/3/3R/12/4/4X	3 ft. [0.91 m]	140G-K-FMXB03	6 ft. [1.9 m]	140G-K-FMXB06	
		4 ft. [1.3 m]	140G-K-FMXB04	10 ft. [3.0 m]	140G-K-FMXB06	
	Stainless Steel Handle, Type 4/4X	3 ft. [0.91 m]	140G-K-FCSB03	6 ft. [1.9 m]	140G-K-FCSB06	
		4 ft. [1.3 m]	140G-K-FCSB04	10 ft. [3.0 m]	140G-K-FCSB06	

Description	Frame Size	Catalog Number
EZ Plate - eliminates precision drilling and tapping for MCCB mounting screws. Kit includes plate with mounting fasteners	G & H	140G-G-EZ
	I, J & K	140G-J-EZ

Allen-Bradley, LISTEN. THINK. SOLVE., Rockwell Automation and Rockwell Software are trademarks of Rockwell Automation, Inc. Trademarks not belonging to Rockwell Automation are property of their respective companies.

www.rockwellautomation.com

Power, Control and Information Solutions Headquarters

Americas: Rockwell Automation, 1201 South Second Street, Milwaukee, WI 53204-2496 USA, Tel: (1) 414.382.2000, Fax: (1) 414.382.4444

Europe/Middle East/Africa: Rockwell Automation NV, Pegasus Park, De Kleetlaan 12a, 1831 Diegem, Belgium, Tel: (32) 2 663 0600, Fax: (32) 2 663 0640

Asia Pacific: Rockwell Automation, Level 14, Core F, Cyberport 3, 100 Cyberport Road, Hong Kong, Tel: (852) 2887 4788, Fax: (852) 2508 1846